



Contact our sales office regarding a delivery date or a price since this is a special model.

SMC P.G.Information (Specialized Product)


SP137X-031E-A
RP:SQ

Electric Actuator/Slider Type Double Table Specifications/LEF※-X61 Series

SMC Corporation
4-14-1, SOTO-KANDA,
CHIYODA-KU,
TOKYO 101-0021, JAPAN
URL: <http://www.smcworld.com>

■Features

- Stable transfer of large workpieces
- Improved allowable moment
- Suitable for simultaneous operation at 2 points
(Coupling the tables is required.)

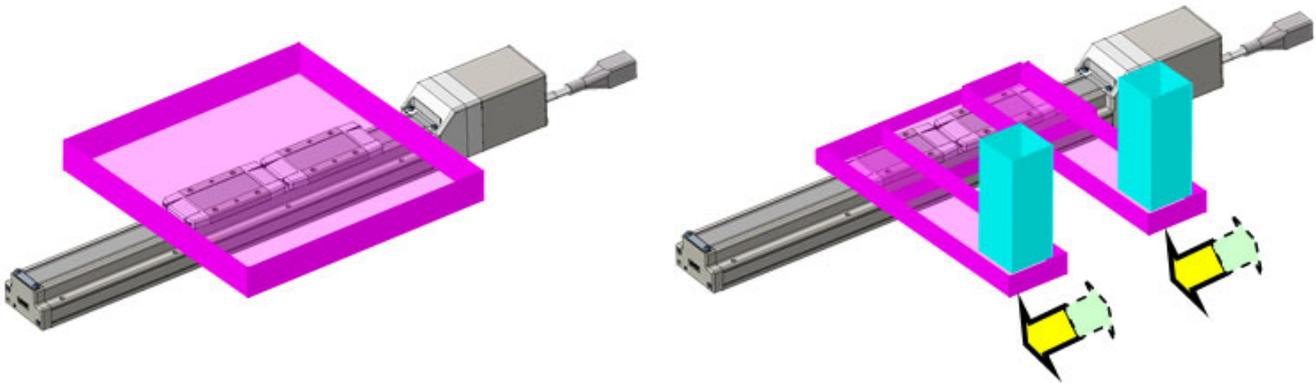

Variations

Size	Motor type	LEFS Ball Screw Drive		LEFB Belt Drive		LEFG Support Guide		
		In-line	Parallel	Top	Bottom	S	BT	BS
16	Step motor	●	●	●	-	●	●	-
	Servo motor	●	●	●	-	●	●	-
	Battery-less absolute	●	●	●	-	●	●	-
25	Step motor	●	●	●	-	●	●	-
	Servo motor	●	●	●	-			
	Battery-less absolute	●	●	●	-			
	AC servo motor	●	●	●	●	-	-	●
32	Motorless	●	●	●	●	●	-	●
	Step motor	●	●	●	-			
	Battery-less absolute	●	●	●	-			
	AC servo motor	●	●	●	●			
40	Motorless	●	●	●	●	●	-	-
	Step motor	●	●	-	-			
	Battery-less absolute	●	●	-	-			
	AC servo motor	●	●	●	●			

Specifications

Specifications other than moment are the same as the standard product.

However, since stroke variations are different from the standard variations, please refer to the attached drawing.

Others

Since allowable moment varies depending on the table interval, please contact us for details.

It is possible to change the table interval.

 Caution To ensure the safest possible operation of this product, please be sure to thoroughly read the "Safety Instructions" in our "Best Pneumatics" catalog before use.